

56 Series Distribution Board

The 56 Series Distribution Board is available in a fully modular design that lets you mix and match from 2 to 16 gangs, with an IP66 rating. You can make your own switchboard by fixing module devices together.

Features


- 4 and 13 modules wide to suit DIN Rail RCDs, MCBs, MCB/RCD and accessories.
- Deep cover for ample wiring room above and below the DIN rail.
- Solid damage resistant cover.
- Cover latches open for easy maintenance.
- Space above MCBs to accept locking off and padlocking accessories.
- IPA identification drill outs.
- Time saving drop in cradle for easier cable installation on 56SB4.




Neutral - Clipsal 56 Series

Catalogue Number	Ui/Ue (Volt)	Module Type	No. of Poles	Module Width	O/A Dimensions			Colour
					L (mm)	W (mm)	D (mm)	
56SB4-GY	240 / 440	1, 2, 3 pole MCB	4 RCD	4 Max	204	101	139	Grey
56CB13-GY	240 / 440	1, 2, 3 pole MCB	4 RCD	13 Max	295	198	123	Grey
56CB13LE-GY	240 / 440	1, 2, 3 pole MCB	4 RCD	13 Max	295	198	123	Grey

Dimensions (mm)

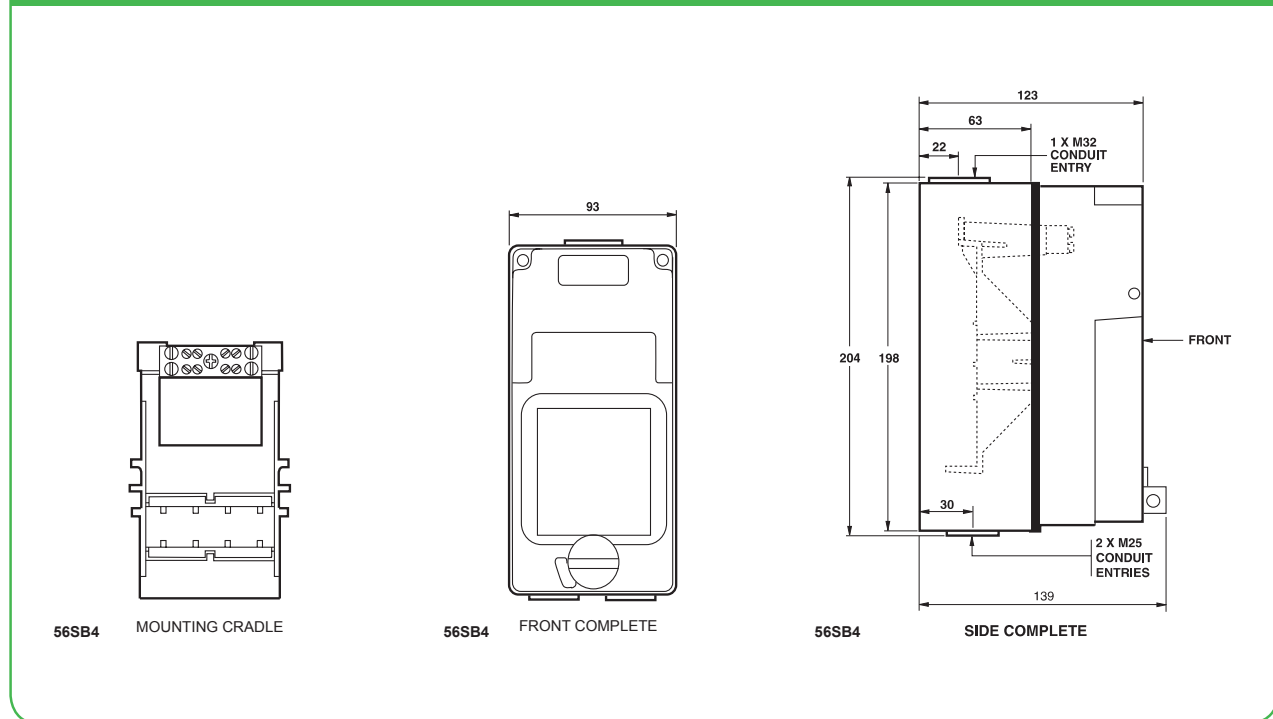

Dimensions (mm)

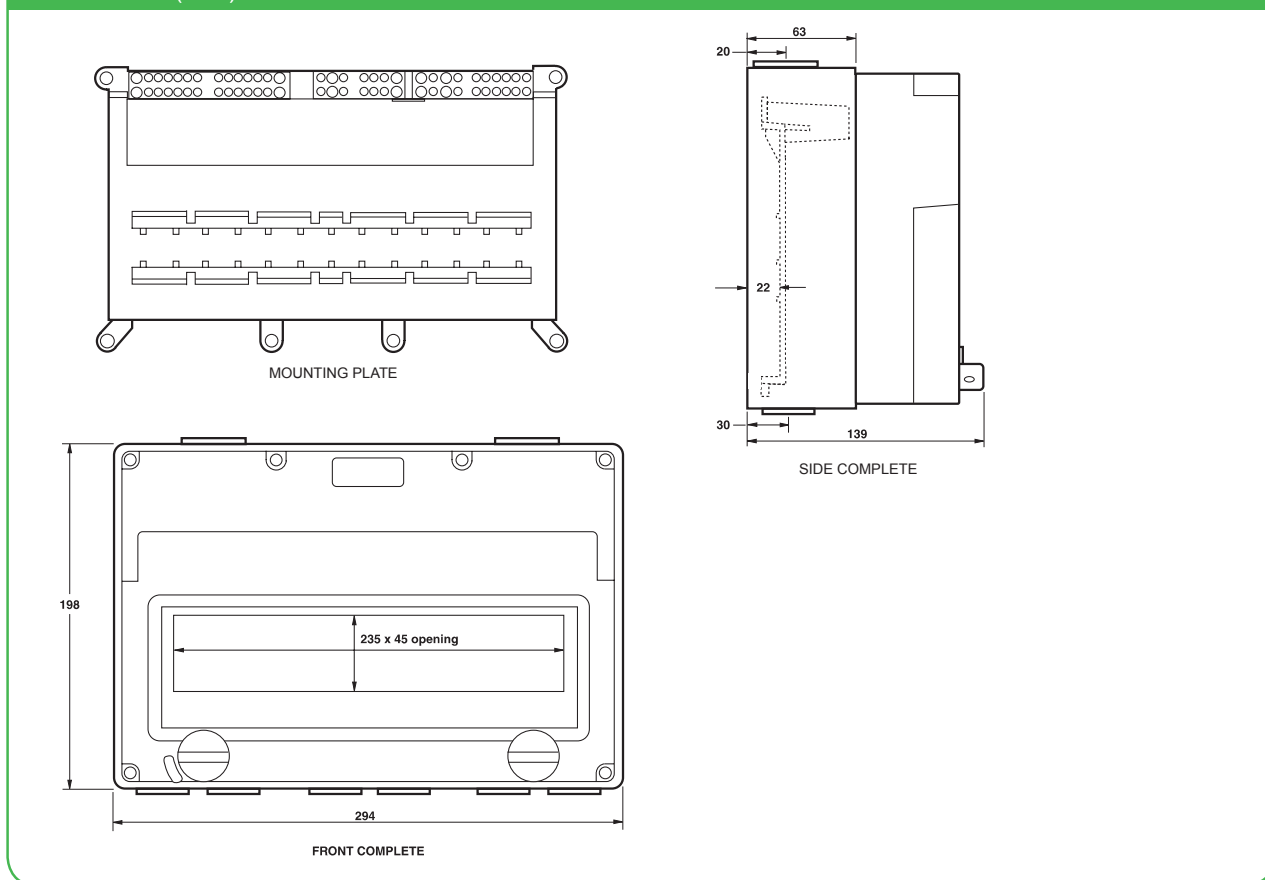

Neutral - PDL 56 Series

Catalogue Number	Ui/Ue (Volt)	Neon Voltage (Volt)	Module Type	No. of Poles	Module Width	O/A Dimensions			Colour
						L (mm)	W (mm)	D (mm)	
PDL56CB13	240 / 440	-	1, 2, 3 pole MCB	4 RCD	13 max	295	198	123	Grey
PDL56CB4LEGY	240 / 440	240 / 415	1, 2, 3 pole MCB	4 RCD	4 Max	190	95	50	Grey

Dimensions (mm)

