


■ 영상전류 검출방식의 지락보호계전기에 적용

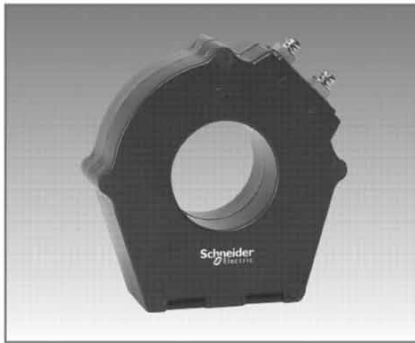

35 Ø



80 Ø




120 Ø


정격사양

Type	관통구경	
ZCT	35	35mm
	80	80mm
	120	120mm
영상 1차측 전류	200mA	
영상 2차측 전류	1.5mA	
허용오차	± 5%	
부 담	10VA	
정격전압	AC600V	
절연내압	2kV	
절연저항	10M Ω (DC500V Megger)	
취 부	Panel	


ZCT-Ø35

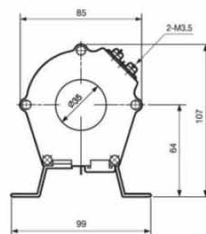

ZCT-Ø80

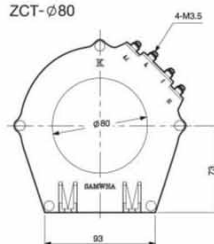

ZCT-Ø120

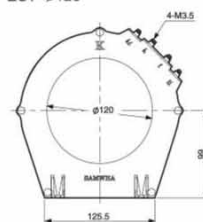

주문방법

Reference		관통구경(mm)	비 고
ZCT	-035	35	35 Ø 형값
	-035T	35	
	-080	80	
	-120	120	

주문예시

예) ZCT를 주문할 경우

Z C T - 0 3 5

①	관통구경	035	35mm
		080	80mm
		120	120mm